



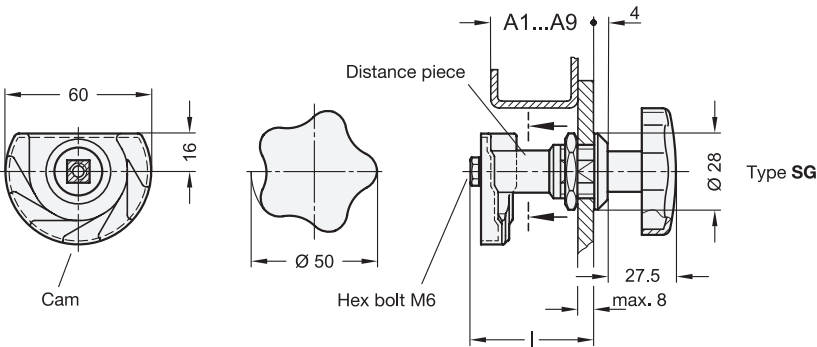

- 1 Type**
- SG** With star knob
 - DK** With triangular spindle
 - VK7** With square spindle
 - VK8** With square spindle
 - VDE** With double bit

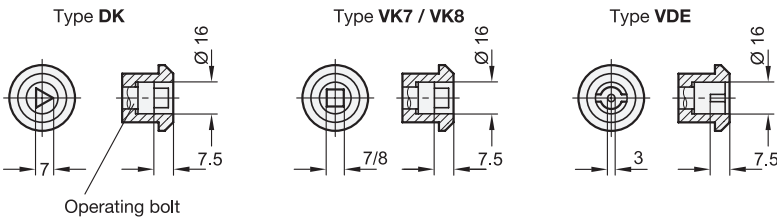

2

Clamping range **A1...A9** (Door thickness + door frame thickness)

A 1 (l = 35)	A 2 (l = 40)	A 3 (l = 45)	A 4 (l = 50)	A 5 (l = 55)	A 6 (l = 60)	A 7 (l = 65)	A 8 (l = 70)	A 9 (l = 75)
17 - 25	22 - 30	27 - 35	32 - 40	37 - 45	42 - 50	47 - 55	52 - 60	57 - 65

Specification

3

- Lock housing / Operating bolt
Stainless steel AISI 303 **NI**
- Cam latch
Stainless sheet steel AISI 304
- Distance piece
Stainless steel AISI 303
- Star knob GN 5334
Stainless steel AISI 304
- Protection class IP 65
- *IP Protection Classes → Page 2153*
- *Stainless Steel Characteristics → Page 2166*
- **RoHS**

Accessory

- Socket Keys GN 119.2 → *Page 1266*
- Protective Caps GN 120 → *Page 1268*
- Opening Handles GN 120.1 → *Page 1269*
- Sheet metal punches GN 123 → *Page XYZ*

Information

Latches GN 119 have a pulling-in range of 10 mm. Locking is achieved by turning the latch clockwise.

The operating bolt is fitted with an O-ring.

see also...

- *Construction and Assembly Instructions → Page 1241*
- *List of Latch Types → Page 1196 ff.*
- *Latches GN 119 (Lock housing, Zinc die casting) → Page 1240*

How to order
GN 119-SG-A3-NI

- | | |
|----------|------------------|
| 1 | Type |
| 2 | Clamping range A |
| 3 | Material |