


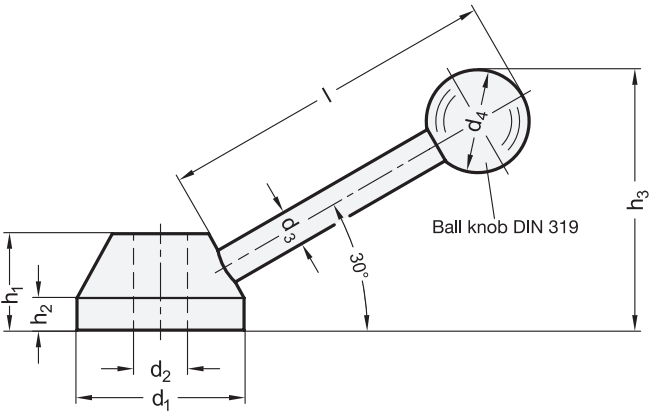

- 2** Bore code
- B** Without keyway
- K** With keyway DIN 6885-1 P9
- V** With square DIN 79

1 d ₁	3 d ₂ Bore H7 Square H11	d ₃	d ₄	h ₁	h ₂	h ₃ ≈	Length l ≈
25	8	6	16	14	5	35	45
32	10	8	20	18	6,5	48	62
40	12	10	30	22	8,5	77	95
52	16	14	40	28	11	96	136

Specification

Hub / Shaft

Steel
Blackened

Ball knobs DIN 319

Plastic, phenolic resin (PF)
Black, shiny finish

RoHS

see also...	Page
GN 750 Control Levers (Steel)	QVX
Technical Information	
Keyways DIN 6885-1	QVX
Squares DIN 79	QVX
ISO Fundamental Tolerances	QVX

How to order	1 d ₁
	2 Bore code
	3 d ₂
GN 223-32-B10	