


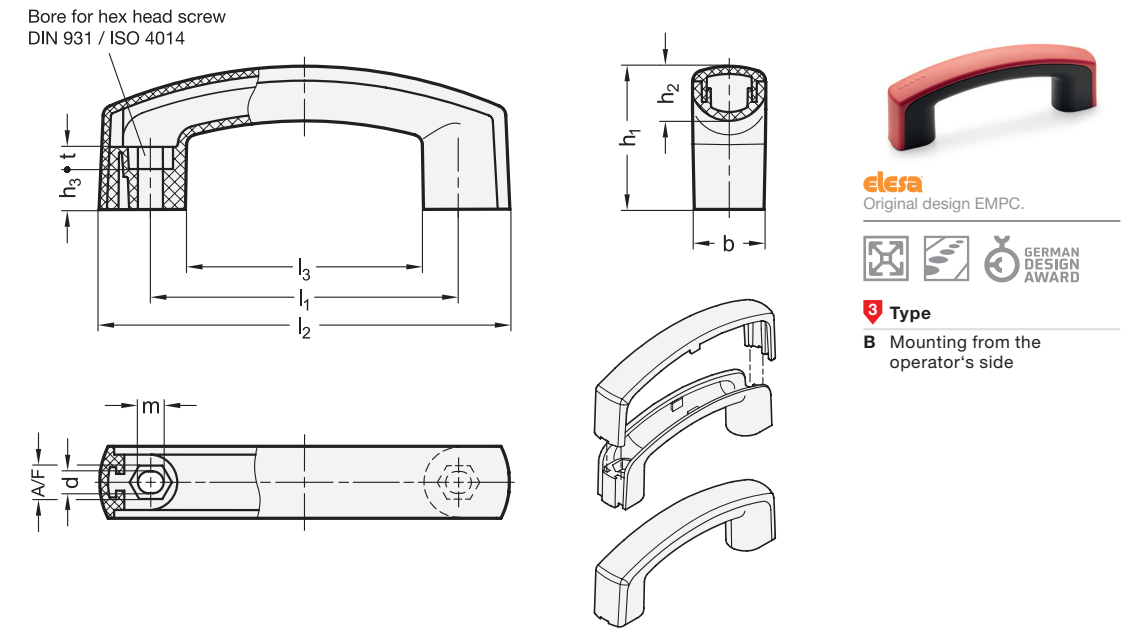

| 1            |             | 2   |    | d    | b  | h <sub>1</sub> | h <sub>2</sub> | h <sub>3</sub> | l <sub>2</sub> | l <sub>3</sub> | m   | A/F | t |
|--------------|-------------|-----|----|------|----|----------------|----------------|----------------|----------------|----------------|-----|-----|---|
| Nominal size | Actual size |     |    |      |    |                |                |                |                |                |     |     |   |
| 117          | 118,5 ±1    | 6,5 | 28 | 54,5 | 21 | 17,5           | 159,5          | 93             | 8              | 10             | 6,5 |     |   |
| 117          | 118,5 ±1    | 8,5 | 28 | 54,5 | 21 | 15,5           | 159,5          | 93             | 10             | 13             | 8,5 |     |   |

Specification

4

Handle

Plastic, Polyamide (PA)

- Glass fiber reinforced
- Operating temperature -30 °C to +130 °C
- Black-gray, matte finish, similar to RAL 7021

Cover cap

Plastic, Polyamide (PA)

- Black-gray, RAL 7021, matte finish
- Orange, RAL 2004, matte finish
- Gray, RAL 7035, matte finish
- Yellow, RAL 1021, matte finish
- Blue, RAL 5024, matte finish
- Red, RAL 3000, matte finish
- Green, RAL 6017, matte finish

- DSG
- DOR
- DGR
- DGB
- DBL
- DRT
- DGN

|                           |     |
|---------------------------|-----|
| Product Family Ergostyle® | QVX |
| Strength Properties       | QVX |
| Plastic Characteristics   | QVX |

|              |                          |
|--------------|--------------------------|
| How to order | 1 l <sub>1</sub>         |
|              | 2 d                      |
|              | 3 Type                   |
|              | 4 Color of the cover cap |