


Fork head DIN 71752

Fork joint GN 751

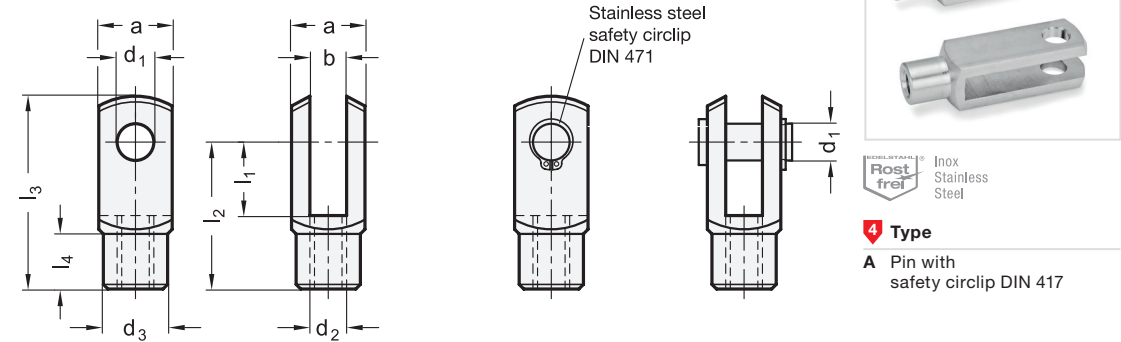

4 Type
A Pin with safety circlip DIN 417

1 d₁ H9/h11	2 l₁	3 d₂	a	b	d₃	l₂	l₃	l₄
4	8 16	M 4	8	4	8	16 24	21 29	6
5	10 20	M 5	10	5	9	20 30	26 36	7,5
6	12 24	M 6	12	6	10	24 36	31 43	9
8	16 32	M 8	16	8	14	32 48	42 58	12
10	20 40	M 10	20	10	18	40 60	52 72	15
12	24 48	M 12	24	12	20	48 72	62 86	18
14	28 56	M 14	28	14	24	56 85	72 101	22,5
16	32 64	M 16	32	16	26	64 96	83 115	24
20	40 -	M 20	40	20	34	80 -	105 -	30

Specification

- Stainless steel AISI 304 Plain **NI**
- Safety circlip DIN 471 Stainless steel German Material No. 1.4122
- ISO Fundamental Tolerances → Page 2151
- Stainless Steel Characteristics → Page 2166
- RoHS

On request

- Fork heads in accordance with DIN 71752 with d₁ = 30 and 35

Information

Fork joints GN 751 consists of a fork head according to DIN 71752 and a pin with one safety circlip DIN 471.

Standard DIN 71752 does not foresee size d₁ = 20.

see also...

- Fork Joints GN 751 (Steel) → Page 1662

How to order (Fork Joint)	1 d ₁
	2 l ₁
	3 d ₂
	4 Type
	5 Material
GN 751-8-16-M8-A-NI	

How to order (Fork Head)	1 d ₁
	2 l ₁
	3 d ₂
	5 Material
DIN 71752-6-24-M6-NI	