


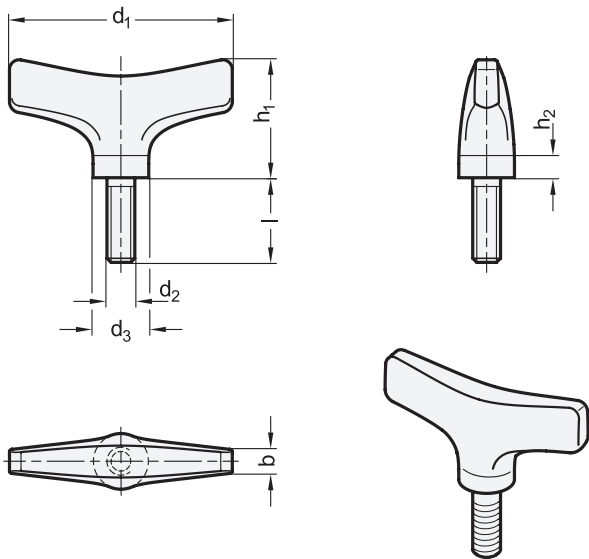

1						2		3			
d ₁	d ₂	Length l				b	d ₃	h ₁	h ₂ ≈		
32	M 5	10	12	16	20	4	9	18	3		
32	M 6	12	16	20	25	4	9	18	3		
40	M 6	12	16	20	25	4	11	21	3		
40	M 8	16	20	25	30	4	11	21	3		
50	M 8	16	20	25	30	6	13	26	3		
50	M 10	20	25	30	40	6	13	26	3		
63	M 10	20	25	30	40	11	16	33	4		
63	M 12	25	30	40	50	11	16	33	4		

Specification

- Stainless steel precision casting AISI 316
 - Matte shot-blasted finish
 - Polished finish
- Stainless Steel Characteristics → Page 2166
- RoHS

4

MT
PL

Information

Wing screws GN 8350 clamp and fasten parts easily without tools. The ergonomic shape allows for high tightening forces.

The wing screws can also be used in particularly aggressive environments thanks to the material used.

see also...

- Wing Screws GN 8351 (Stainless Steel, Hygienic Design) → Page QVX
- Wing Nuts GN 8340 (Stainless Steel) → Page QVX
- Wing Screws GN 431 (Stainless Steel) → Page 621
- Wing Screws GN 433 (Stainless Steel) → Page 620
- Wing Screws GN 835 (Stainless Steel) → Page 619

How to order

1

2

3

4

GN8350-50-M10-30-MT

d₁

d₂

Length l

Finish